


Fibre optic diffuse reflection sensor

FT-00-P-A-M4

Article no longer available - archive entry

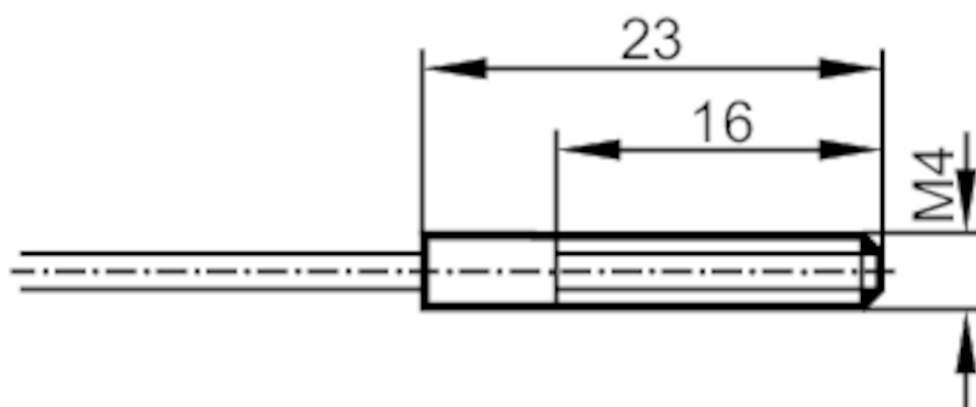

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

20

OUF

Range fibre optics

[mm]

20

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M4

Total length

[mm]

600

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

Fibre head material

aluminium

E20835



Fibre optic diffuse reflection sensor

FT-00-P-A-M4

Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.