


Fibre optic diffuse reflection sensor

FT-00-P-A-M6

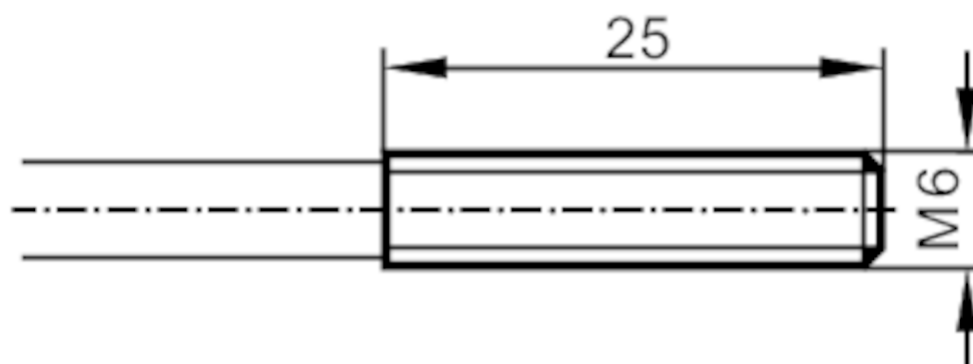

Application

Function principle

Diffuse reflection sensor

Application

Для використання у промисловості

Detection zone

Range with fibre optic
amplifier type

OCF; OKF; OOF; OUF

OCF (High Power)

Range fibre optics

[mm]

330

OKF

Range fibre optics

[mm]

40

OOF

Range fibre optics

[mm]

200

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

42.5

Version of sensing head

straight

Sensing head thread

M6

E20051



Fibre optic diffuse reflection sensor

FT-00-P-A-M6

Sensing head length	[mm]	25
Total length	[mm]	600; (+20 mm)
Min. bending radius	[mm]	20
Fibre arrangement		⓪
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC

Аксессуары

Items supplied	hexagon nuts: 2 x M6, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M11

Remarks

Pack quantity	1 pcs.
---------------	--------