




Fibre optic diffuse reflection sensor

FT-00-P-A-E3

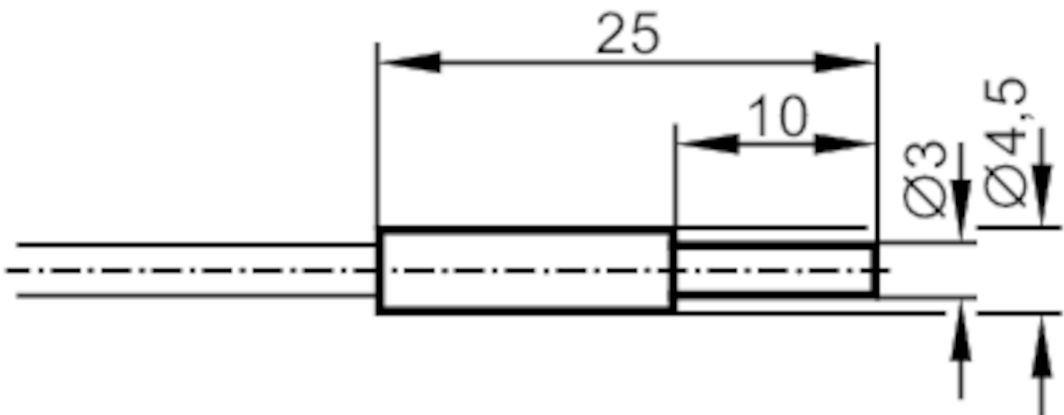

Application		
Function principle		Diffuse reflection sensor
Application		Для використання у промисловості
Detection zone		
Range with fibre optic amplifier type		OKF; OUF; OOF
OKF		
Range fibre optics	[mm]	40
OOF		
Range fibre optics	[mm]	200
OUF		
Range fibre optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	46
Version of sensing head		straight
Sensing head diameter	[mm]	3
Sensing head length	[mm]	25
Total length	[mm]	600

E20052



Fibre optic diffuse reflection sensor

FT-00-P-A-E3

Min. bending radius	[mm]	20
Fibre arrangement		
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Аксессуары		
Items supplied		E20105
Remarks		
Pack quantity		1 pcs.