




Fibre optic diffuse reflection sensor

FT-00-P-V-E1

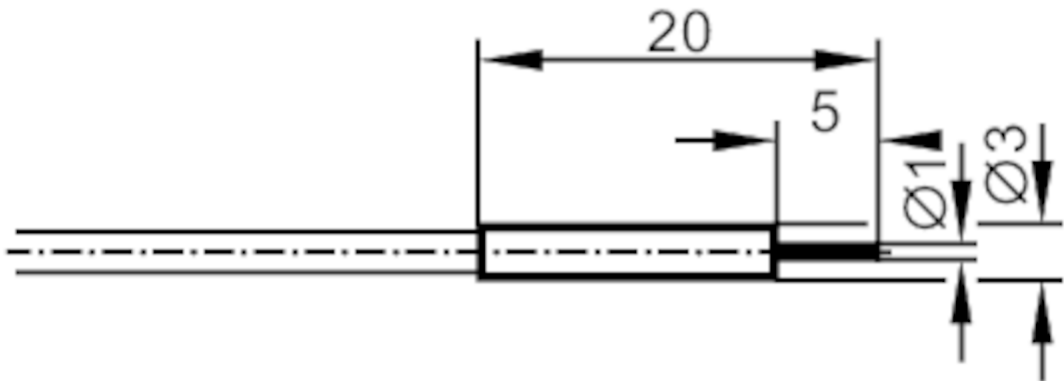

Application		
Function principle		Diffuse reflection sensor
Application		Для використання у промисловості
Detection zone		
Range with fibre optic amplifier type		OCF; OKF; OOF; OUF
OCF (High Power)		
Range fibre optics	[mm]	40
OKF		
Range fibre optics	[mm]	8
OOF		
Range fibre optics	[mm]	24
OUF		
Range fibre optics	[mm]	8
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	37.5
Version of sensing head		straight
Sensing head diameter	[mm]	1

E20053



Fibre optic diffuse reflection sensor

FT-00-P-V-E1

Sensing head length	[mm]	5
Total length	[mm]	600
Min. bending radius	[mm]	20
Fibre arrangement		①
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)
Fibre sheath material		PVC

Аксессуары

Items supplied	Mounting clamp:, E20107
----------------	-------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------