


Fibre optic diffuse reflection sensor

FT-00-P-A-R4

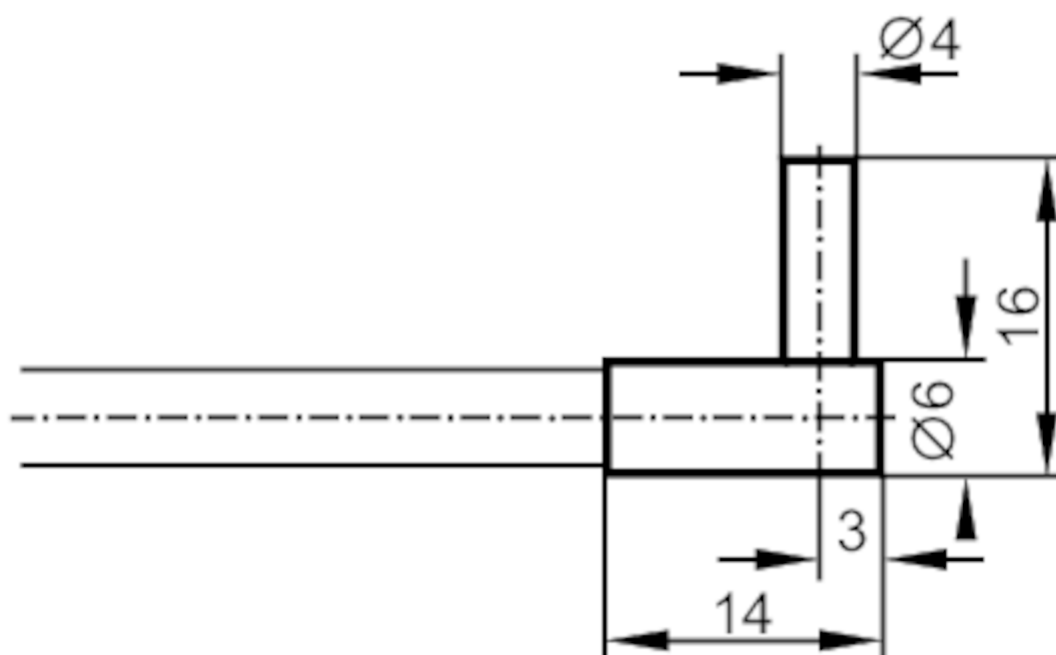

Application

Function principle

Diffuse reflection sensor

Application

Для використання у промисловості

Detection zone

Range with fibre optic
amplifier type

OCF; OKF; OOF; OUF

OCF (High Power)

Range fibre optics

[mm]

340

OKF

Range fibre optics

[mm]

40

OOF

Range fibre optics

[mm]

200

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

47

Version of sensing head

angled

Sensing head diameter

[mm]

4

E20054



Fibre optic diffuse reflection sensor

FT-00-P-A-R4

Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20
Fibre arrangement		①
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC

Аксессуары

Items supplied	E20103
----------------	--------

Remarks

Pack quantity	1 pcs.
---------------	--------