




Fibre optic diffuse reflection sensor

FT-00-A-A-M6

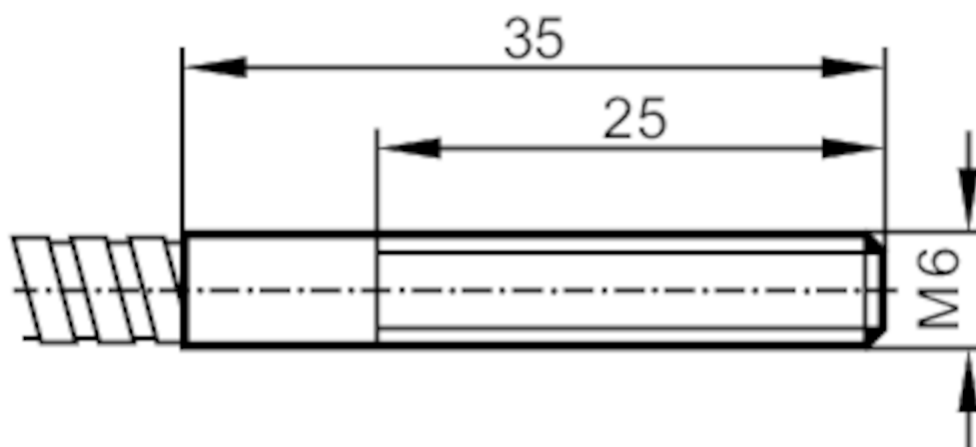

Application

Function principle

Diffuse reflection sensor

Application

Висока стійкість до температури; Міцне виконання
для використання у важких умовах експлуатації

Detection zone

Range with fibre optic
amplifier type

OKF; OUF; OOF; OCF

OCF

Range fibre optics

[mm]

330

OKF

Range fibre optics

[mm]

40

OOF

Range fibre optics

[mm]

200

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Weight

[g]

48.5

Version of sensing head

straight

Sensing head thread

M6

E20055



Fibre optic diffuse reflection sensor

FT-00-A-A-M6

Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		⓪
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Аксессуары		
Items supplied		hexagon nuts: 2 x M6, stainless steel
		tooth lock washers: 2
		knurled nut: 1 x M11
Remarks		
Pack quantity		1 pcs.