




Fibre optic diffuse reflection sensor

FT-00-A-A-E3

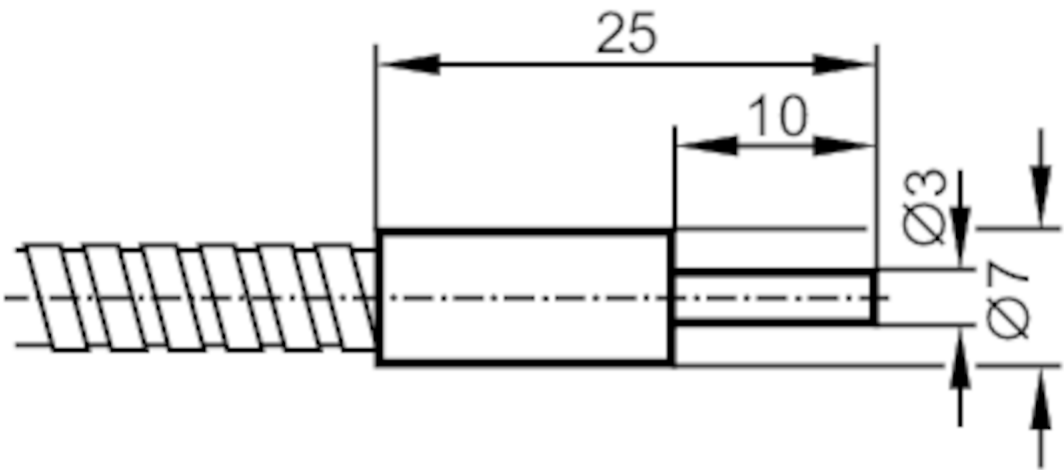

Application	
Function principle	Diffuse reflection sensor
Application	Висока стійкість до температури; Міцне виконання для використання у важких умовах експлуатації
Detection zone	
Range with fibre optic amplifier type	OCF; OKF; OOF; OUF
OCF (High Power)	
Range fibre optics [mm]	310
OKF	
Range fibre optics [mm]	40
OOF	
Range fibre optics [mm]	200
OUF	
Range fibre optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Weight [g]	51.5
Version of sensing head	straight
Sensing head diameter [mm]	3

E20056



Fibre optic diffuse reflection sensor

FT-00-A-A-E3

Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		①
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Аксессуары		
Items supplied		E20102
Remarks		
Pack quantity		1 pcs.