


Fibre optic diffuse reflection sensor

FT-00-A-V-E1

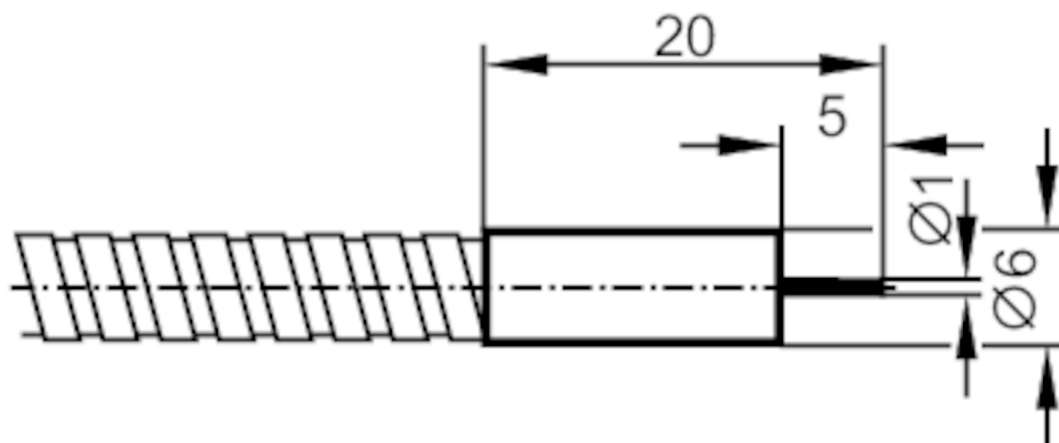

Application

Function principle

Diffuse reflection sensor

Application

Висока стійкість до температури; Міцне виконання
для використання у важких умовах експлуатації

Detection zone

Range with fibre optic
amplifier type

OCF; OKF; OOF; OUF

OCF (High Power)

Range fibre optics

[mm]

40

OKF

Range fibre optics

[mm]

8

OOF

Range fibre optics

[mm]

24

OUF

Range fibre optics

[mm]

8

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Weight

[g]

46

Version of sensing head

straight

Sensing head diameter

[mm]

1

E20057



Fibre optic diffuse reflection sensor

FT-00-A-V-E1

Sensing head length	[mm]	5
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		①
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)
Fibre sheath material		aluminium

Аксессуары

Items supplied	E20103
----------------	--------

Remarks

Pack quantity	1 pcs.
---------------	--------