


Fibre optic diffuse reflection sensor

FT-00-M-E3

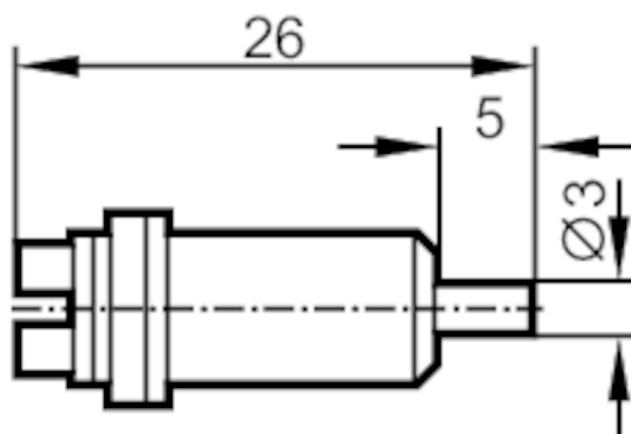

Application

Function principle	Diffuse reflection sensor
Application	Для використання у промисловості

Detection zone

Range with fibre optic amplifier type	OCF; OKF; OUF
---------------------------------------	---------------

OCF (High Power)

Range fibre optics [mm]	360
-------------------------	-----

OKF

Range fibre optics [mm]	40
-------------------------	----

OUF

Range fibre optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Weight [g]	12.5
Version of sensing head	straight
Sensing head diameter [mm]	3
Total length [mm]	26
Fibre arrangement	ⓘ

E20078



Fibre optic diffuse reflection sensor

FT-00-M-E3

Fibre material	glass
Fibre head material	brass
Remarks	
Pack quantity	1 pcs.