




Fibre optic diffuse reflection sensor

FT-00-P-A-M6/1M

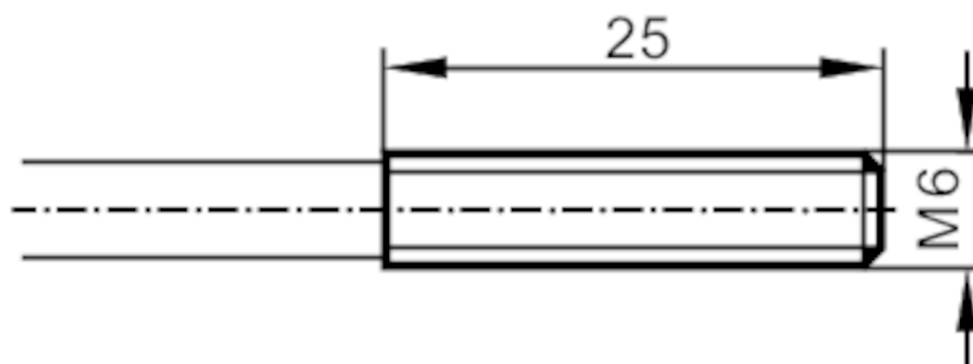

Application

Function principle	Diffuse reflection sensor
Application	Для використання у промисловості

Detection zone

Range with fibre optic amplifier type	OCF; OKF; OUF
---------------------------------------	---------------

OCF (High Power)

Range fibre optics [mm]	340
-------------------------	-----

OKF

Range fibre optics [mm]	40
-------------------------	----

OUF

Range fibre optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Weight [g]	50
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	25
Total length [mm]	1000

E20083



Fibre optic diffuse reflection sensor

FT-00-P-A-M6/1M

Min. bending radius	[mm]	20
Fibre arrangement		
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Аксессуары		
Items supplied		hexagon nuts: 2 x M6, stainless steel
		tooth lock washers: 2
		knurled nut: 1 x M11
Remarks		
Pack quantity		1 pcs.