




Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,5M

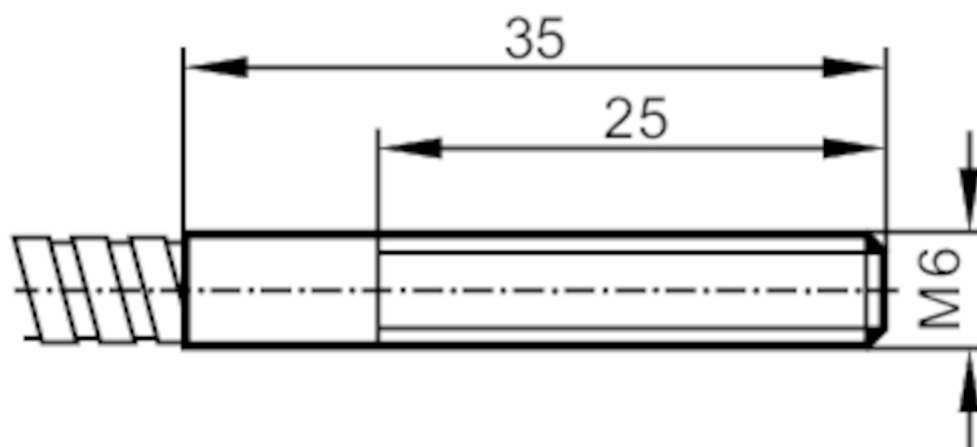

Application

Function principle

Diffuse reflection sensor

Application

Висока стійкість до температури; Міцне виконання
для використання у важких умовах експлуатації

Detection zone

Range with fibre optic
amplifier type

OCF; OKF; OUF

OCF (High Power)

Range fibre optics

[mm]

270

OKF

Range fibre optics

[mm]

36

OUF

Range fibre optics

[mm]

36

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Weight

[g]

72.5

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

1500

E20086



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,5M

Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Аксессуары		
Items supplied		hexagon nuts: 2 x M6, stainless steel
		tooth lock washers: 2
		knurled nut: 1 x M11
Remarks		
Pack quantity		1 pcs.