


Fibre optic through-beam sensor

FE-00-A-A-E3

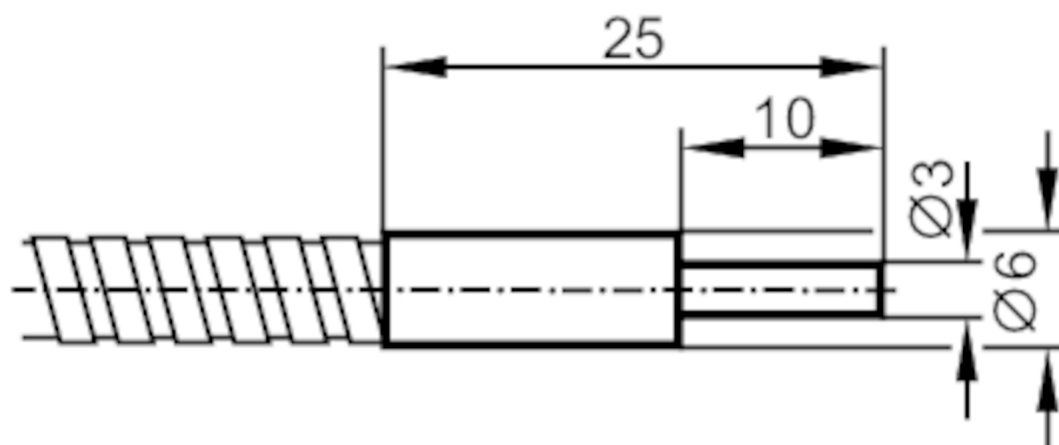

Application

Function principle

Through-beam sensor

Application

Висока стійкість до температури; Міцне виконання
для використання у важких умовах експлуатації

Detection zone

Range with fibre-optic
amplifier type

OCF; OKF; OOF; OUF

OCF (High Power)

Range of fibre optics

[mm]

1200

OKF

Range of fibre optics

[mm]

120

OOF

Range of fibre optics

[mm]

400

OUF

Range of fibre optics

[mm]

120

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Weight

[g]

69

Version of sensing head

straight

Sensing head diameter

[mm]

3

E20130



Fibre optic through-beam sensor

FE-00-A-A-E3

Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium

Аксессуары

Items supplied	E20103
----------------	--------

Remarks

Pack quantity	1 pcs.
---------------	--------