


Fibre optic diffuse reflection sensor

FT-30-A-A-M8/3M

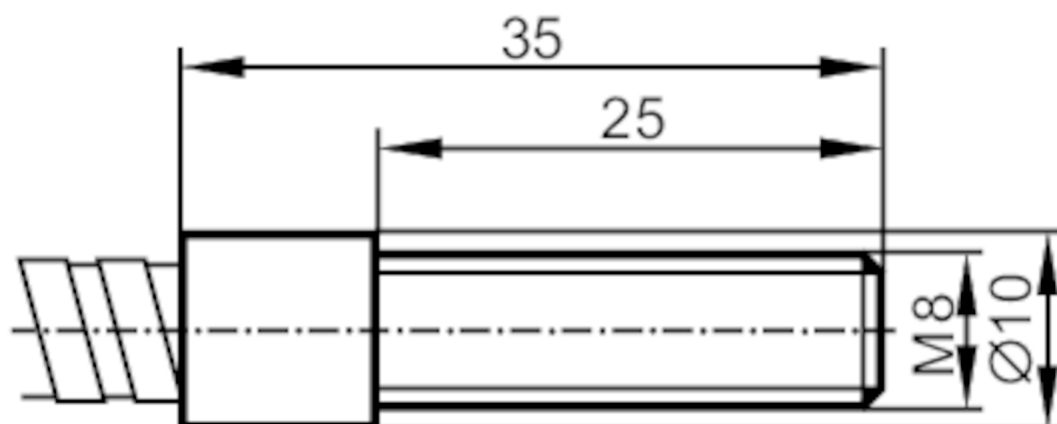

Application

Function principle

Diffuse reflection sensor

Application

Висока стійкість до температури; Міцне виконання
для використання у важких умовах експлуатації

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics [mm]

45

Operating conditions

Ambient temperature [°C]

-40...290

Mechanical data

Weight [g]

239.7

Version of sensing head

straight

Sensing head thread

M8

Total length [mm]

3000

Min. bending radius [mm]

30; (for fixed installation)

Fibre arrangement



Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

E20137



Fibre optic diffuse reflection sensor

FT-30-A-A-M8/3M

Fibre sheath material	aluminium
Аксессуары	
Items supplied	hexagon nuts: 2 x M8, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.