




Fibre optic diffuse reflection sensor

FT-30-A-A-M8/2M

phase-out article

Alternative articles: E20137
When selecting an alternative article and accessories please note that technical data may differ!

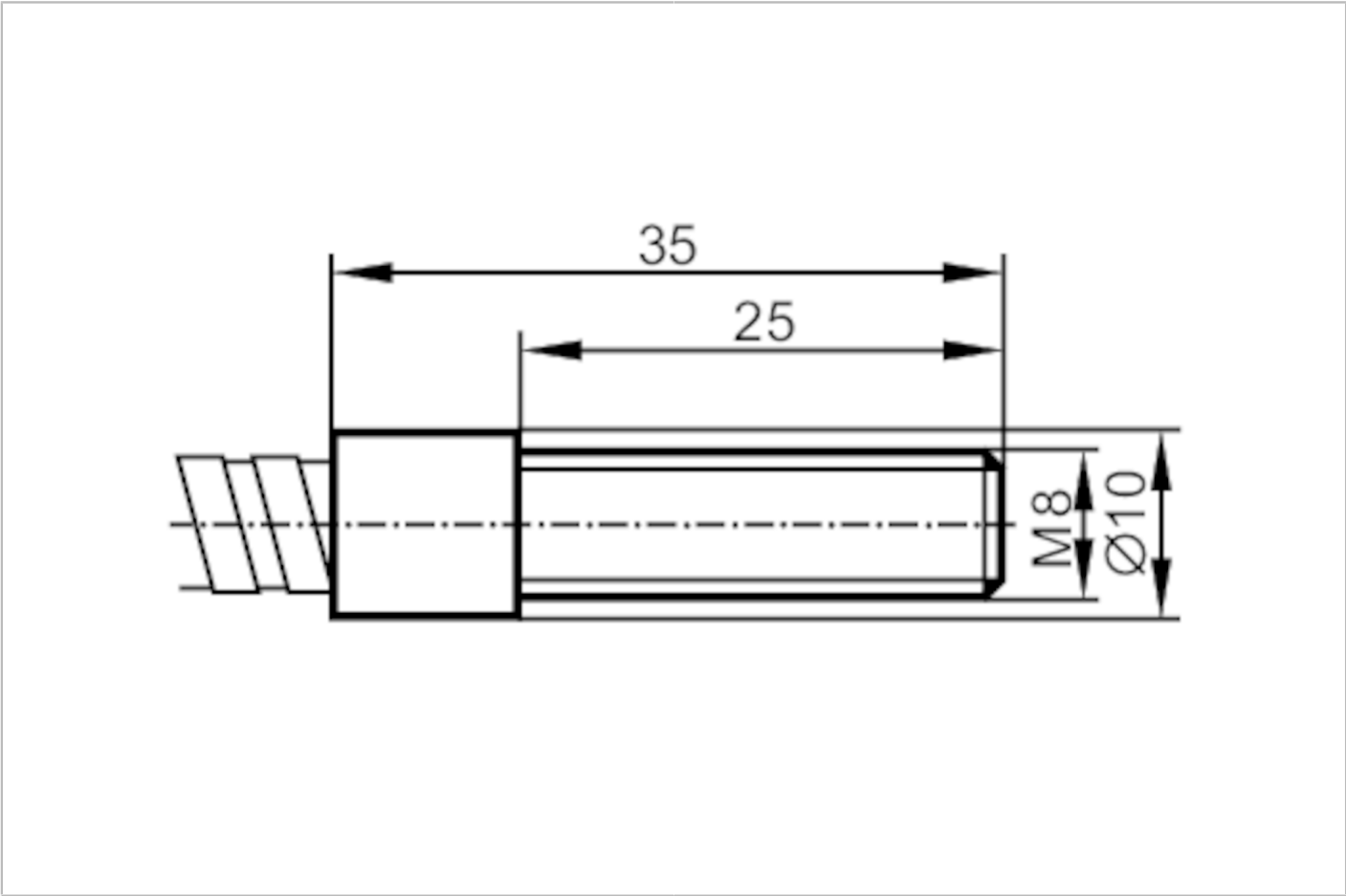

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	56
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Weight [g]	164
Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	2000
Min. bending radius [mm]	30; (for fixed installation)
Fibre arrangement	⓪

E20148



Fibre optic diffuse reflection sensor

FT-30-A-A-M8/2M

Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium
Аксессуары	
Items supplied	hexagon nuts: 2 x M8, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.