




Fibre optic diffuse reflection sensor

FT-30-A-A-R8

Article no longer available - archive entry

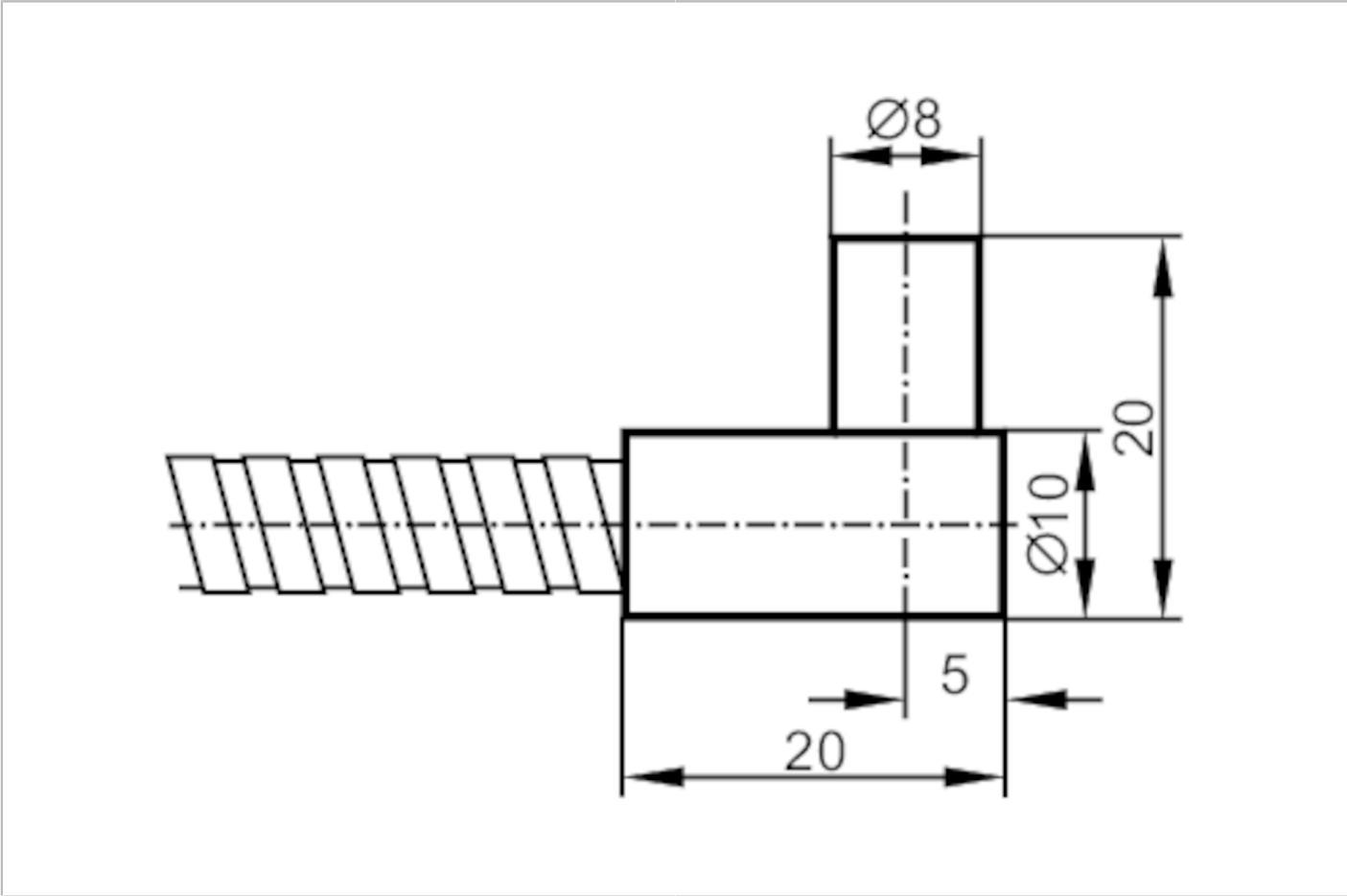

Application	
Function principle	Diffuse reflection sensor
Application	Висока стійкість до температури; Міцне виконання для використання у важких умовах експлуатації
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	70
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Weight [g]	93.8
Version of sensing head	angled
Sensing head diameter [mm]	8
Total length [mm]	600
Min. bending radius [mm]	30; (for fixed installation)
Fibre arrangement	⓪
Materials	Adapter: PA

E20153



Fibre optic diffuse reflection sensor

FT-30-A-A-R8

Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium
Аксессуары	
Items supplied	E20353
Remarks	
Pack quantity	1 pcs.