


Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,15m

Article no longer available - archive entry

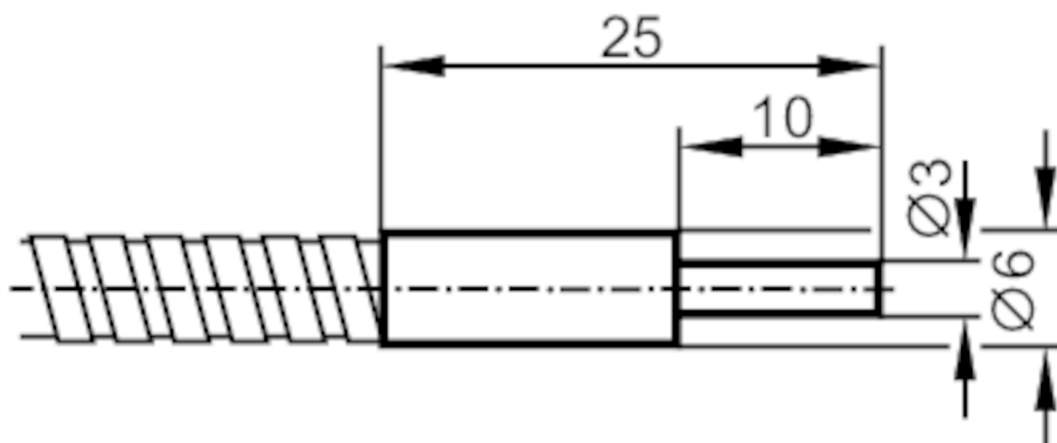

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	40
-------------------------	----

OUF

Range fibre optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	straight
-------------------------	----------

Sensing head diameter [mm]	3
----------------------------	---

Sensing head length [mm]	10
--------------------------	----

Total length [mm]	150
-------------------	-----

Min. bending radius [mm]	20
--------------------------	----

Materials	Adapter: ABS
-----------	--------------

Fibre material	glass
----------------	-------

E20185



Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,15m

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.