


Fibre optic through-beam sensor

FE-30-P-A-M6/1M

Article no longer available - archive entry

Alternative articles: E20217

When selecting an alternative article and accessories please note that technical data may differ!

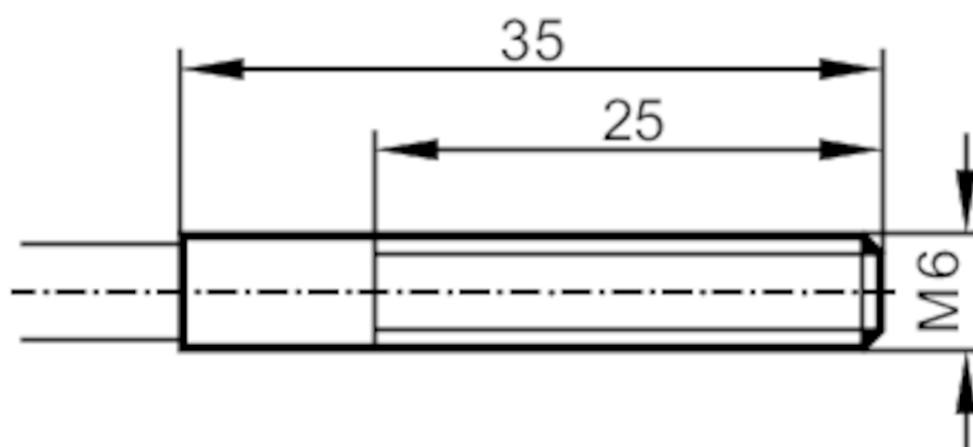

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OIF

OIF

Range of fibre optics

[mm]

300

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

1000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

E20193



Fibre optic through-beam sensor

FE-30-P-A-M6/1M

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.