


Fibre optic through-beam sensor

FE-00-P-A-R3

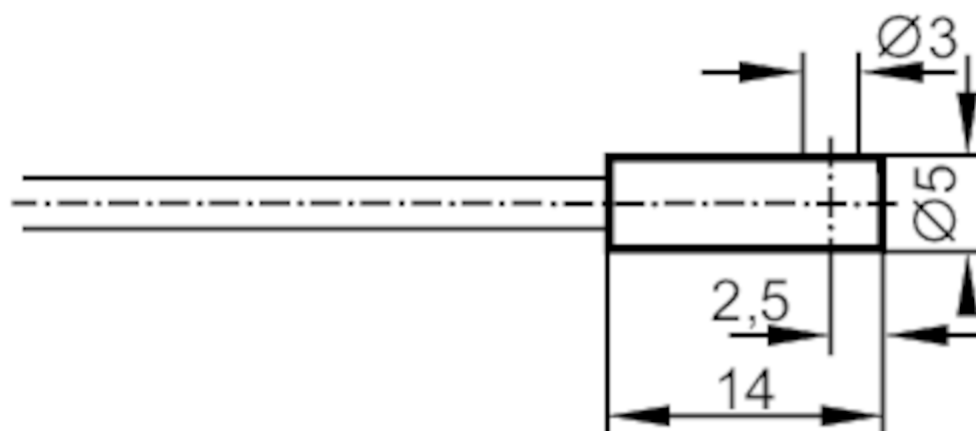

Application

Design	90° deflection of the light beam
Function principle	Through-beam sensor
Application	Для використання у промисловості

Detection zone

Range with fibre-optic amplifier type	OKF; OUF; OOF
---------------------------------------	---------------

OKF

Range of fibre optics	[mm]	120
-----------------------	------	-----

OOF

Range of fibre optics	[mm]	400
-----------------------	------	-----

OUF

Range of fibre optics	[mm]	120
-----------------------	------	-----

Operating conditions

Ambient temperature	[°C]	-20...80
---------------------	------	----------

Mechanical data

Weight	[g]	54.5
Version of sensing head		angled
Sensing head diameter	[mm]	5
Total length	[mm]	600

E20228



Fibre optic through-beam sensor

FE-00-P-A-R3

Min. bending radius	[mm]	20
Fibre arrangement		
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Аксессуары		
Items supplied		E20104
Remarks		
Pack quantity		1 pcs.