




Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Article no longer available - archive entry

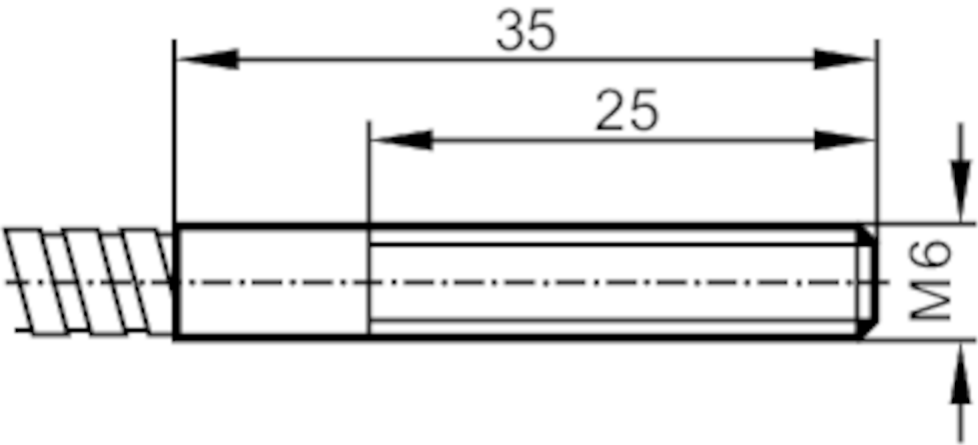

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	30
OUF	
Range fibre optics [mm]	30
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	600
Min. bending radius [mm]	20
Materials	Adapter: ABS
Fibre material	glass

E20257



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.