


Fibre optic diffuse reflection sensor

FT-30-A-A-E6/3M

Article no longer available - archive entry

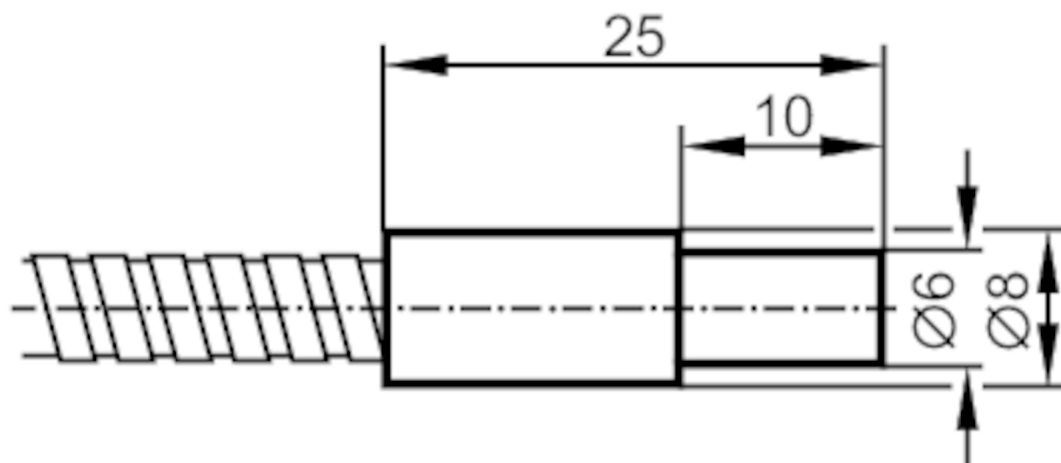

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics

[mm]

27

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

6

Total length

[mm]

3000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

aluminium

E20272



Fibre optic diffuse reflection sensor

FT-30-A-A-E6/3M

Аксессуары	
Items supplied	Mounting clamp:, E10221
Remarks	
Pack quantity	1 pcs.