


Fibre optic through-beam sensor

FE-00-P-A-M4/2,5M

Article no longer available - archive entry

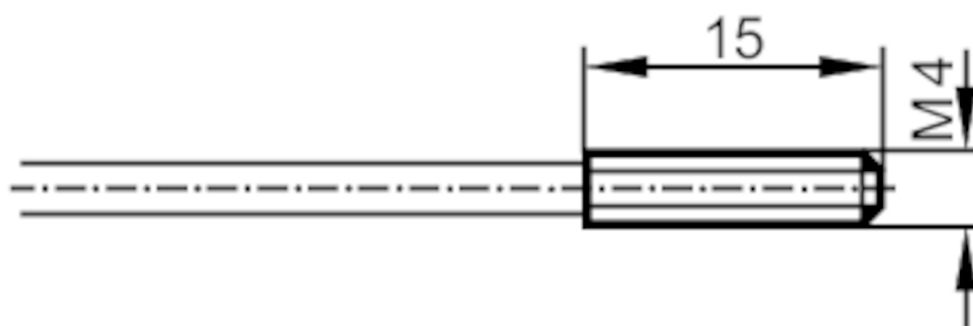

Application

Function principle	Through-beam sensor
--------------------	---------------------

Detection zone

Range with fibre-optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range of fibre optics [mm]	85
----------------------------	----

OUF

Range of fibre optics [mm]	85
----------------------------	----

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M4
Sensing head length [mm]	15
Total length [mm]	2500
Min. bending radius [mm]	10
Materials	Adapter: PPE
Fibre material	glass

E20284



Fibre optic through-beam sensor

FE-00-P-A-M4/2,5M

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.