




Fibre optic through-beam sensor

FE-30-A-A-R3/1.5M

Article no longer available - archive entry

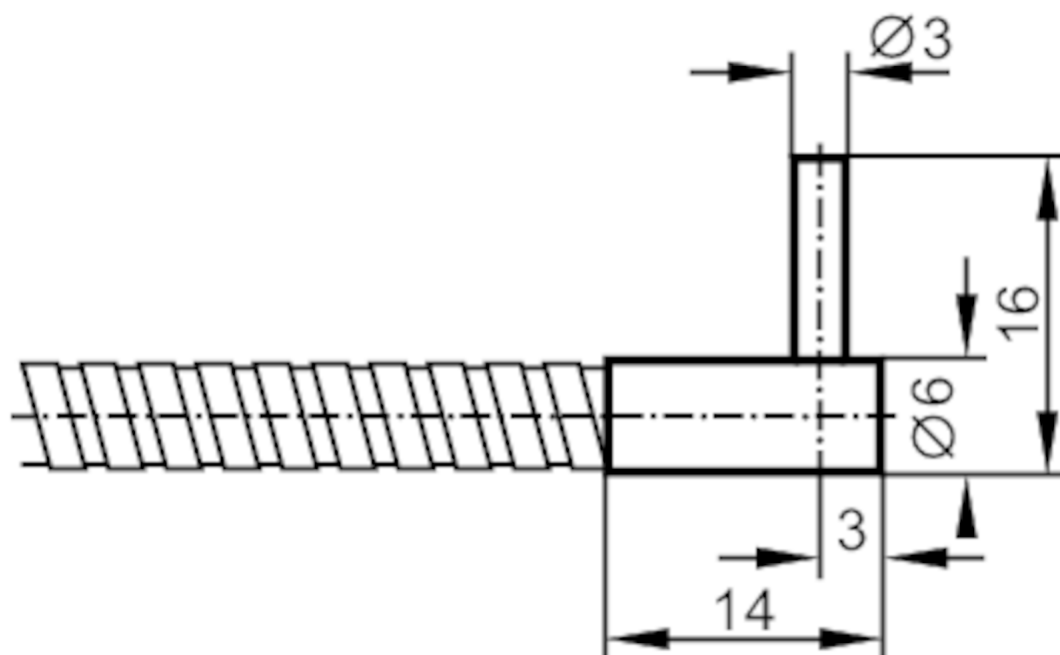

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OIF

OIF

Range of fibre optics

[mm]

90

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Total length

[mm]

1500

Min. bending radius

[mm]

30

Fibre arrangement



Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

aluminium

E20309



Fibre optic through-beam sensor

FE-30-A-A-R3/1.5M

Аксессуары	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.