




Fibre optic through-beam sensor

FE-30-P-A-M6/3m

Article no longer available - archive entry

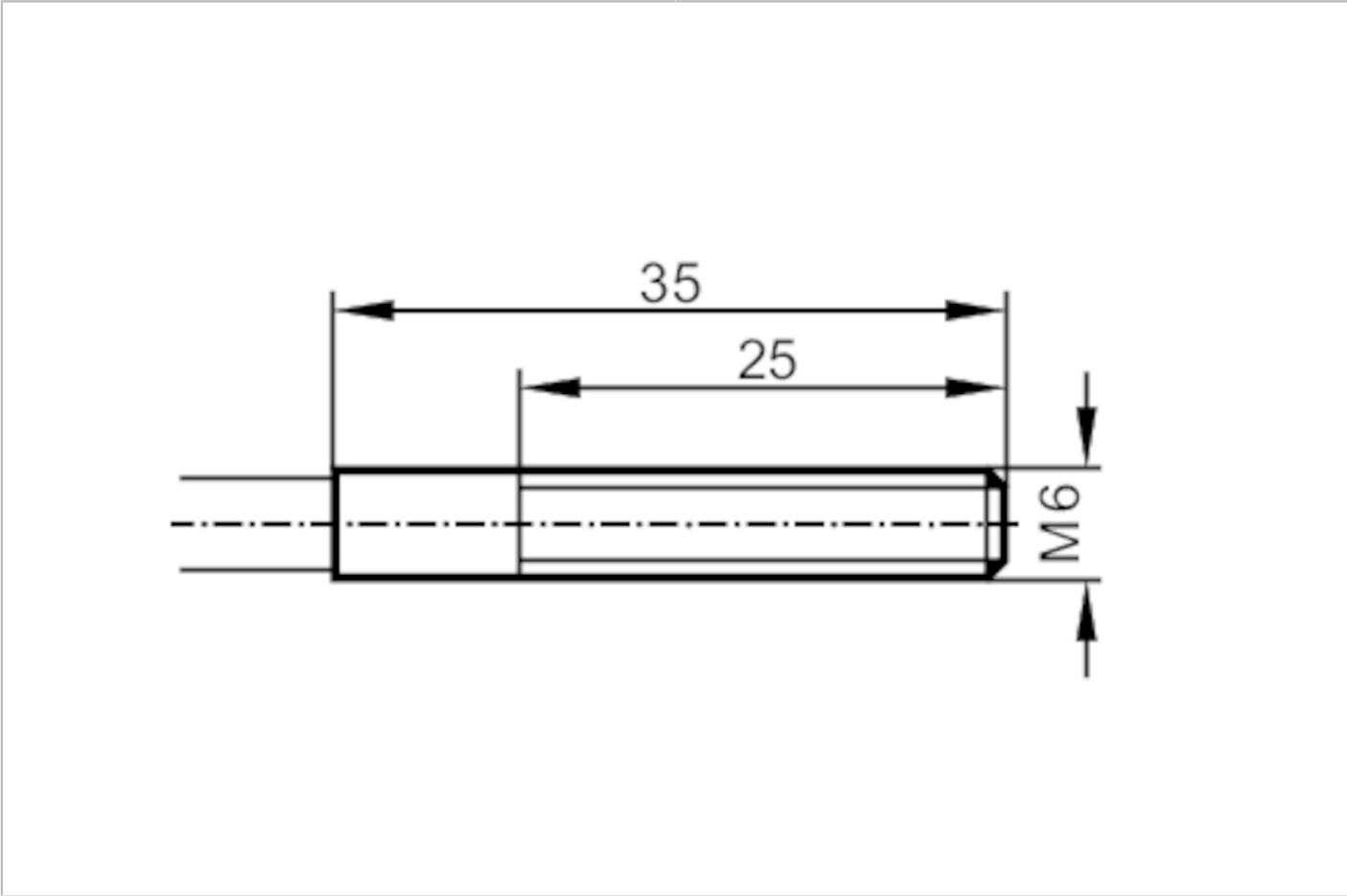

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OIF
OIF	
Range of fibre optics [mm]	192
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	3000
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC

E20327



Fibre optic through-beam sensor

FE-30-P-A-M6/3m

Remarks

Pack quantity	1 pcs.
---------------	--------