


Fibre optic through-beam sensor

FE-30-A-A-E3/1m

Article no longer available - archive entry

Alternative articles: E20347

When selecting an alternative article and accessories please note that technical data may differ!

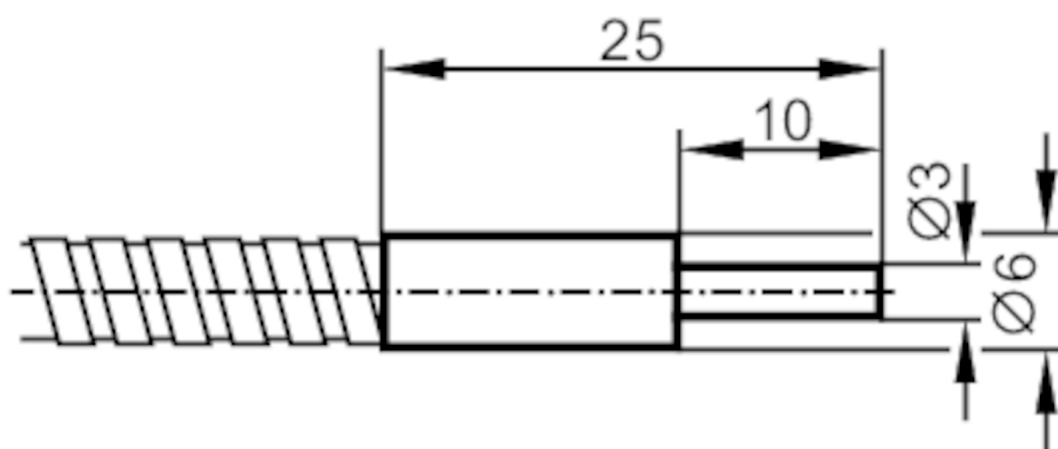

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OIF

OIF

Range of fibre optics

[mm]

100

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Total length

[mm]

1000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

E20345



Fibre optic through-beam sensor

FE-30-A-A-E3/1m

Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.