


Fibre optic through-beam sensor

FE-00-A-A-R3/2,5M

Article no longer available - archive entry

Alternative articles: E20129

When selecting an alternative article and accessories please note that technical data may differ!

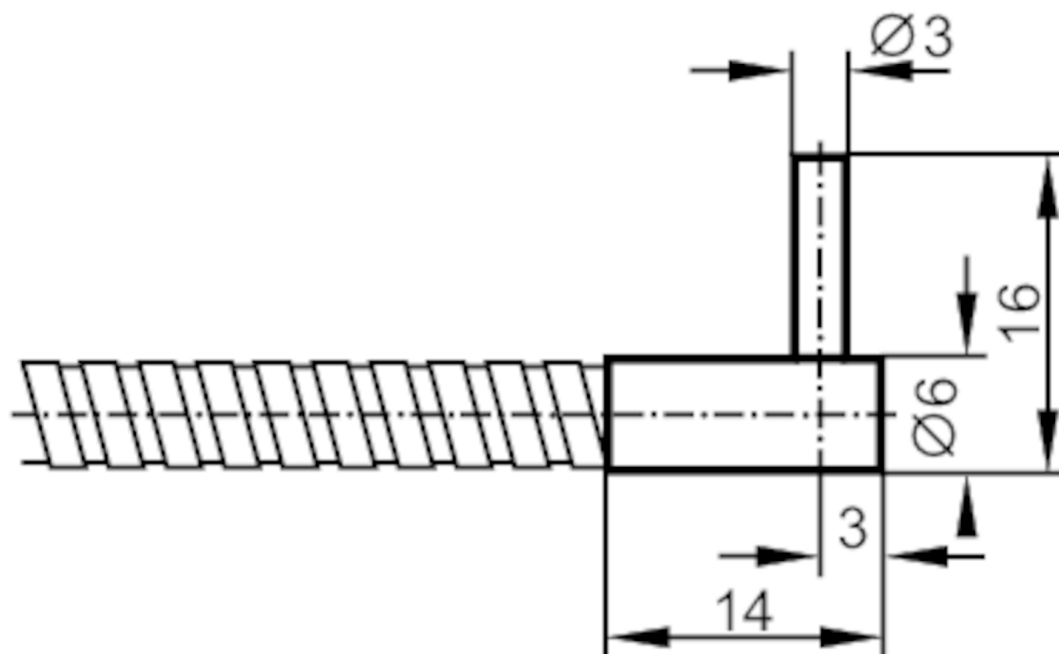

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

85

OUF

Range of fibre optics

[mm]

85

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

2500

E20366



Fibre optic through-beam sensor

FE-00-A-A-R3/2,5M

Min. bending radius	[mm]	20
Materials	Adapter: ABS	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	aluminium	
Remarks		
Pack quantity	1 pcs.	