


Fibre optic diffuse reflection sensor

FT-18-A-A-M6

Article no longer available - archive entry

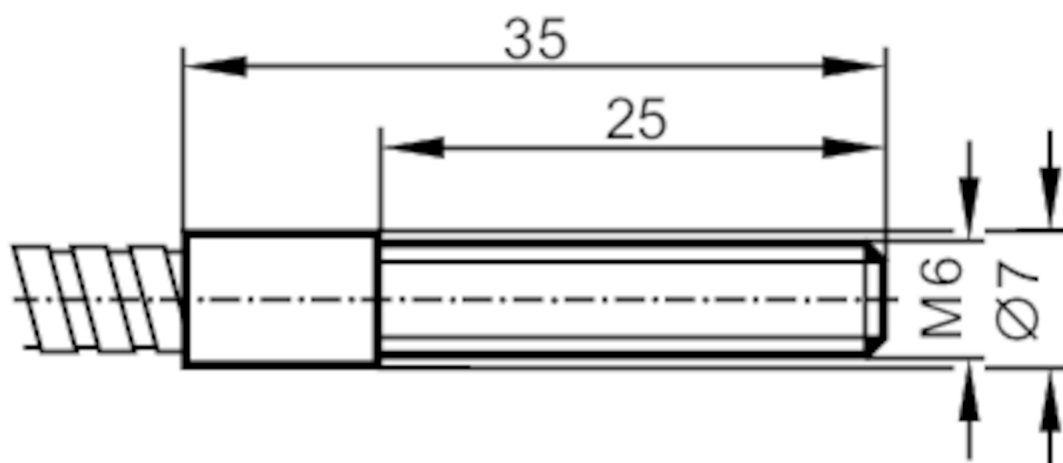

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OGF

OGF

Range fibre optics

[mm]

15

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Weight

[g]

0.055

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

25

Total length

[mm]

600

Min. bending radius

[mm]

20; (for fixed installation)

Fibre arrangement



Materials

Adapter: PPE

Fibre material

glass

E20385



Fibre optic diffuse reflection sensor

FT-18-A-A-M6

Fibre head material	aluminium
Fibre sheath material	aluminium
Аксессуары	
Items supplied	hexagon nuts: 2 x M6, stainless steel
	tooth lock washers: 2
Remarks	
Pack quantity	1 pcs.