




Fibre optic diffuse reflection sensor

FT-18-A-A-R5

Article no longer available - archive entry

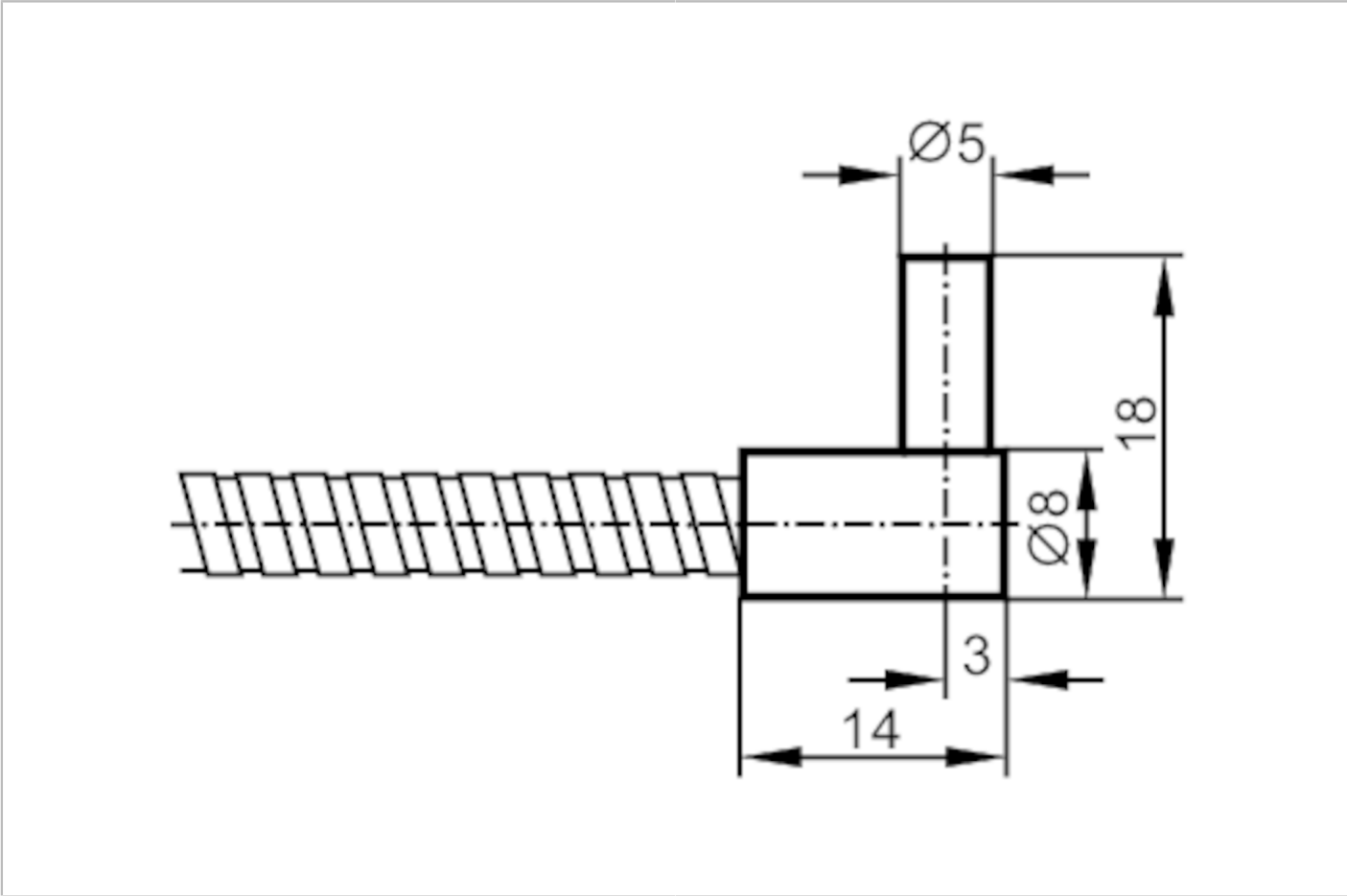

Application		
Function principle		Diffuse reflection sensor
Detection zone		
Range with fibre optic amplifier type		OGF
OGF		
Range fibre optics	[mm]	12
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	0.061
Version of sensing head		angled
Sensing head diameter	[mm]	5
Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		Ⓢ
Materials		Adapter: PPE
Fibre material		glass

E20386



Fibre optic diffuse reflection sensor

FT-18-A-A-R5

Fibre head material	aluminium
Fibre sheath material	PVC
Аксессуары	
Items supplied	Mounting clamp:, E10221
Remarks	
Pack quantity	1 pcs.