


Fibre optic through-beam sensor

FE-18-A-A-M4

Article no longer available - archive entry

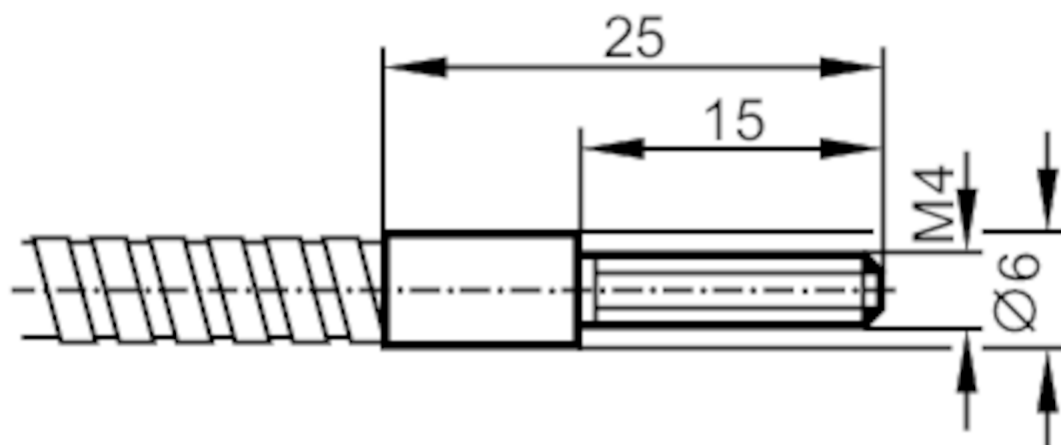

Application

Function principle	Through-beam sensor
--------------------	---------------------

Detection zone

Range with fibre-optic amplifier type	OGF
---------------------------------------	-----

OGF

Range of fibre optics [mm]	80
----------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Weight [g]	0.059
Version of sensing head	straight
Sensing head thread	M4
Sensing head length [mm]	15
Total length [mm]	600
Min. bending radius [mm]	20; (for fixed installation)
Fibre arrangement	●
Materials	Adapter: PPE
Fibre material	glass

E20389



Fibre optic through-beam sensor

FE-18-A-A-M4

Fibre head material	aluminium
Fibre sheath material	aluminium
Аксессуары	
Items supplied	hexagon nuts: 4 x M4
	tooth lock washers: 4
Remarks	
Pack quantity	1 pcs.