


Fibre optic diffuse reflection sensor

FT-30-A-A-M8/1,5M

Article no longer available - archive entry

Alternative articles: E20137

When selecting an alternative article and accessories please note that technical data may differ!

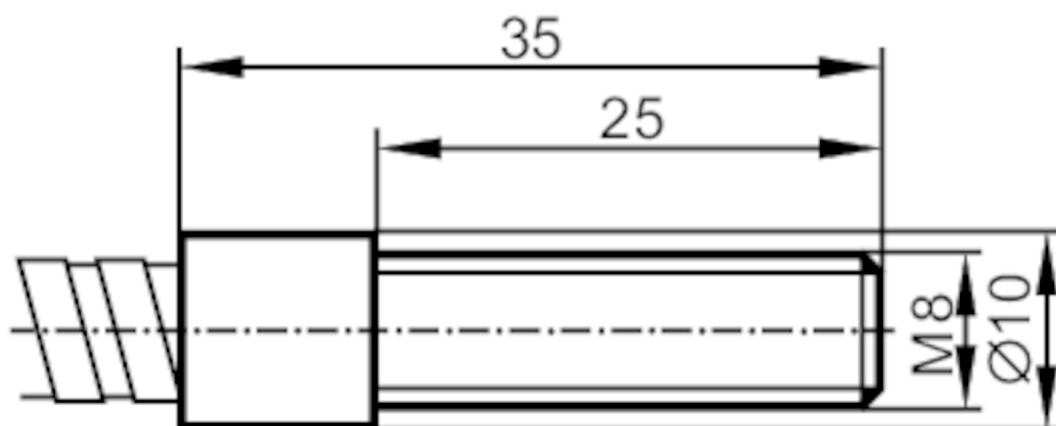

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics

[mm]

63

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head thread

M8

Total length

[mm]

1500

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

E20392



Fibre optic diffuse reflection sensor

FT-30-A-A-M8/1,5M

Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.