


E21010



Cable gland

CABLE GLAND M20 SKINTOP

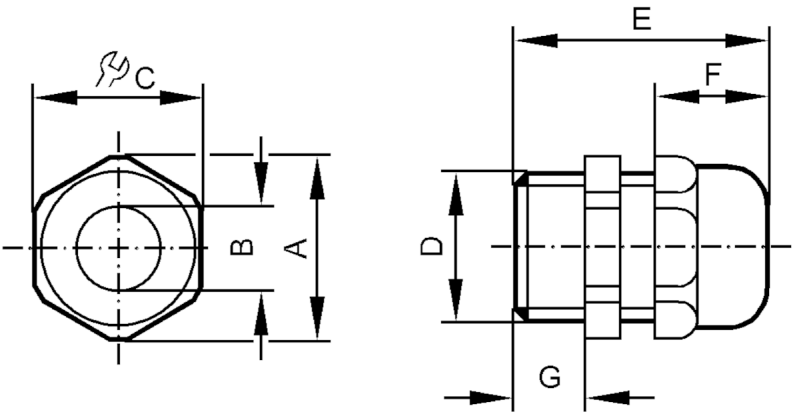

A	28
B	5...10
C	25
D	M20 x 1.5
E	38
F	17

Operating conditions

Ambient temperature	[°C]	-25...100
---------------------	------	-----------

Mechanical data

Weight	[g]	12.2
Dimensions	[mm]	M20 x 1.5
Thread designation		M20 x 1.5
Materials		housing: PA black; Sealing: CR
Length	[mm]	38

Remarks

Pack quantity	1 pcs.
---------------	--------