


E21138



Ethernet connection cable

VSTGN040ZDS0002L04STGN040ZDS

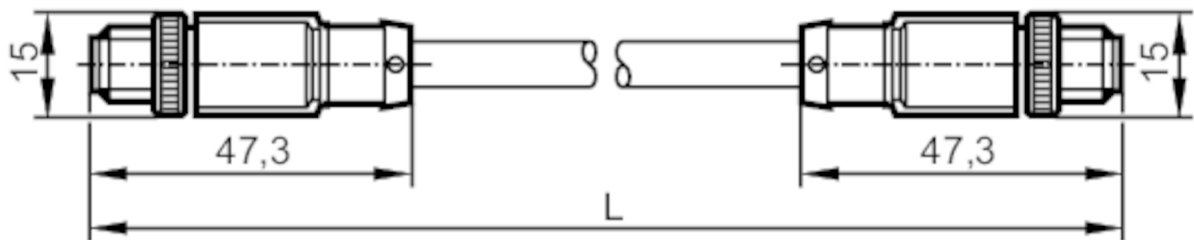

Application		
Special feature		Gold-plated contacts; Screened cable
Design		Ethernet cable, D-coded
Electrical data		
Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-20...90
Protection		IP 67
Mechanical data		
Weight	[g]	163.6
Dimensions	[mm]	15 x 15 x 47.3
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E21138



Ethernet connection cable

VSTGN040ZDS0002L04STGN040ZDS

Electrical connection - plug


Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected



Electrical connection

Cable: 2 m, PVC, green, shielded; 4 x 0.34 mm²

Connection

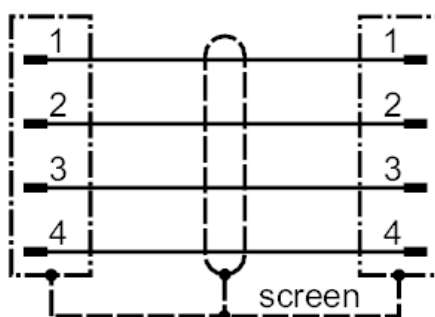

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

