


E2M200



Adapter cables for cameras with video output

ADAPTER CABLE M12-M16

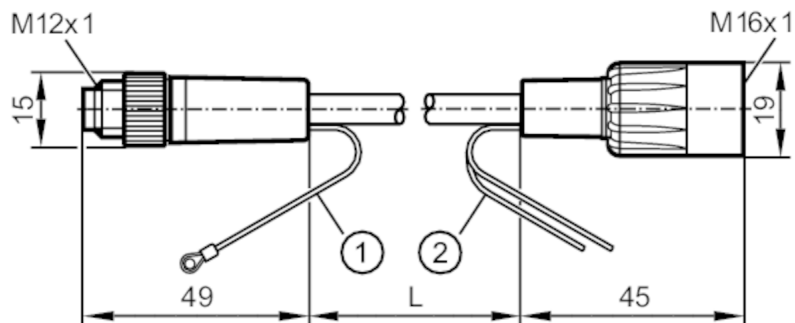

- 1 screen L= 120
2 подача напруги L= 250

Application

Special feature	Free from silicone; Gold-plated contacts
Design	camera with video output O2M20x
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-45...85
Protection		IP 67

Mechanical data

Weight	[g]	72.4
Mounting thread		M16
Materials		housing: PVC; Sealing: EPDM
Material nut		PVC

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.6 m, PVC, black, Ø 6 mm; 3 x 0.34 mm² / AWG 22 + 1 x 0.11 mm² / AWG 26

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

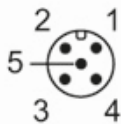




Adapter cables for cameras with video output

ADAPTER CABLE M12-M16

Connection

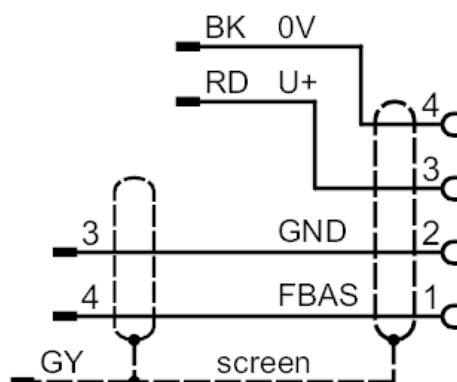

Core colours :
 BK = black
 GY = grey
 RD = red

Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

