


E2M203



Adapter cables for cameras with video output

CONNECTION CABLE M16 5M

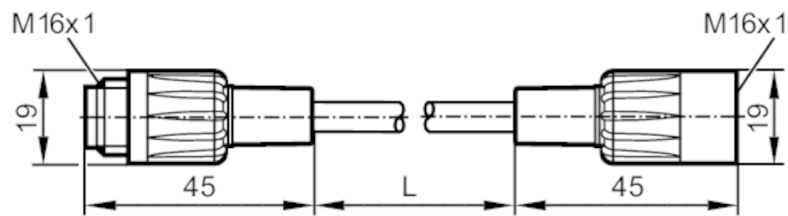

Application		
Special feature		Free from silicone; Gold-plated contacts
Design		camera with video output O2M20x
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 DC
Protection class		II
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-45...85
Protection		IP 67
Mechanical data		
Weight	[g]	307.5
Materials		housing: PVC; Sealing: EPDM
Material nut		PVC
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm




Adapter cables for cameras with video output

CONNECTION CABLE M16 5M

Electrical connection

Cable: 5 m, PVC, black, Ø 6 mm; 3 x 0.34 mm² / AWG 22 + 1 x 0.11 mm² / AWG 26

Connection

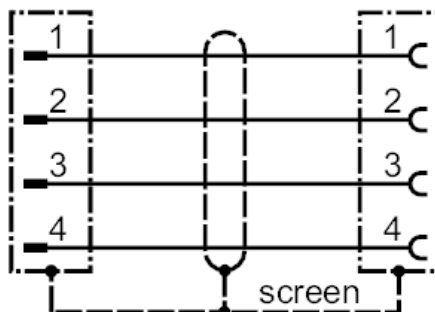

Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

