


# E2M204



## Adapter cables for cameras with video output

CONNECTION CABLE M16 11M

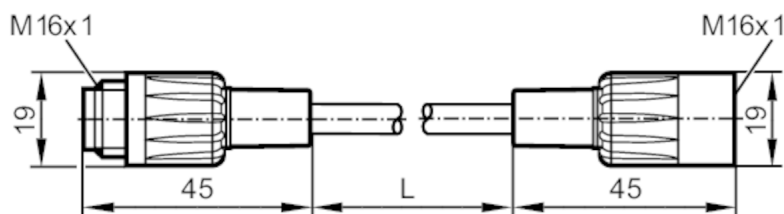

### Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Design             | camera with video output O2M20x          |
| Free from silicone | yes                                      |

### Electrical data

|                         |     |         |
|-------------------------|-----|---------|
| Operating voltage       | [V] | < 60 DC |
| Protection class        |     | II      |
| Max. current load total | [A] | 4       |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -45...85 |
| Protection          |      | IP 67    |

### Mechanical data

|              |     |                             |
|--------------|-----|-----------------------------|
| Weight       | [g] | 589.5                       |
| Materials    |     | housing: PVC; Sealing: EPDM |
| Material nut |     | PVC                         |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection

Cable: 11 m, PVC, black, Ø 6 mm; 3 x 0.34 mm<sup>2</sup> / AWG 22 + 1 x 0.11 mm<sup>2</sup> / AWG 26

### Electrical connection - plug

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm




## Adapter cables for cameras with video output

CONNECTION CABLE M16 11M

### Electrical connection

#### Connection

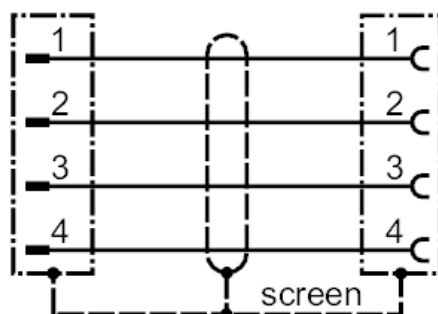

### Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

