


E2M206



Adapter cables for cameras with video output

CONNECTION CABLE M16 21 M

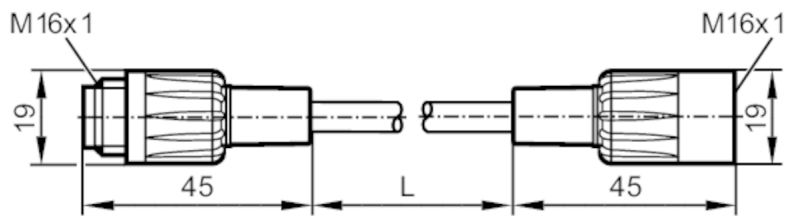


Application	
Special feature	Free from silicone; Gold-plated contacts
Design	camera with video output O2M20x
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 DC
Protection class	II
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-45...85
Protection	IP 67
Mechanical data	
Weight [g]	1093
Materials	housing: PVC; Sealing: EPDM
Material nut	PVC
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 21 m, PVC, black, Ø 6 mm; 3 x 0.34 mm ² / AWG 22 + 1 x 0.11 mm ² / AWG 26	
Electrical connection - plug	
Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm	

Adapter cables for cameras with video output

CONNECTION CABLE M16 21 M

Electrical connection

Connection

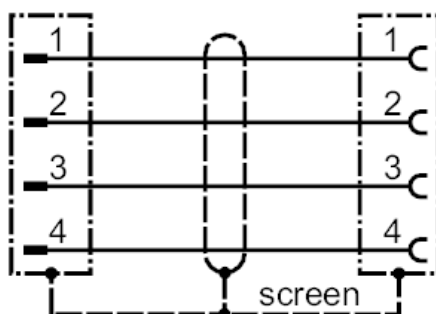

Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

