


E2M235

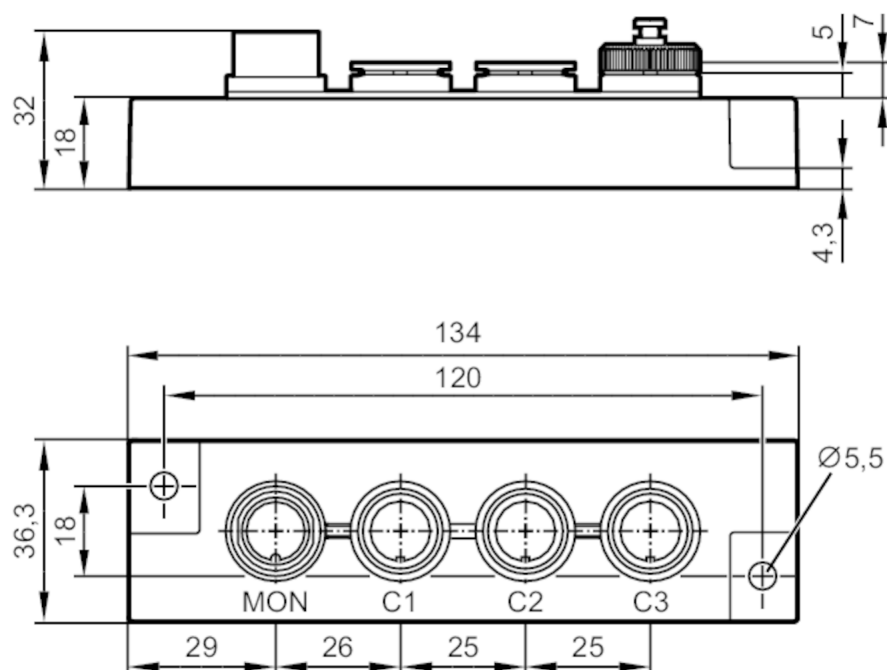

Video Switcher

VIDEO SWITCHER/3 PORT



Electrical data

Operating voltage	[V]	12 DC; ($\pm 1,5V$)
Overvoltage protection		yes

Operating conditions

Ambient temperature	[°C]	-40...85
Storage temperature	[°C]	-40...125
Storage humidity	[%]	< 75; (relative humidity)
Shelf life	[MON]	24
Protection		IP 67

Mechanical data

Weight	[g]	149
Materials		housing: ABS black

Аксессуары

Items supplied		Protective covers
----------------	--	-------------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

 


Video Switcher

VIDEO SWITCHER/3 PORT

Electrical connection - plug

Connector: M16; coding: A



MON

1	coax cable core video signal
2	coax screen video GND
3	not used
4	not used

Electrical connection - socket

Connector: M16; coding: A



C1...3

1	coax cable core video signal
2	coax screen video GND
3	U+
4	0 V