


E2M251




Anschlusskabel für Multiviewbox E2M250

CONNECTION CABLE M16 8P 3,85M

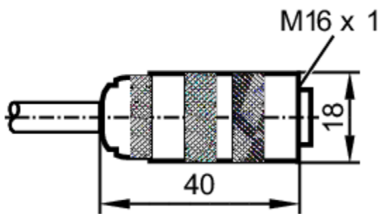

Application		
Special feature	Halogen-free; Drag chain suitability	
Design	Для підключення MultiViewBox E2M250	
Electrical data		
Operating voltage	[V]	< 60 DC
Operating conditions		
Ambient temperature	[°C]	-45...85
Protection	IP 67	
Mechanical data		
Weight	[g]	322.8
Materials	housing: diecast zinc; Sealing: PBT	
Material nut	diecast zinc	
Drag chain suitability	yes	
Drag chain suitability	bending radius for fixed installation	≥ 100 mm
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 3.85 m, PUR, Halogen-free, black, Ø 6 mm; 7 x 0.34 mm²		
Electrical connection - socket		
Connector: 1 x M16, straight; coding: A; Locking: diecast zinc		

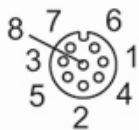

1	12 / 24 V DC red
2	GND white
3	IN 1 blue
4	IN 2 brown
5	IN 3 white/yellow
6	IN 4 grey
7	not used
8	not used