

E30080




Plug-in power supply

POWER SUPPLY 24V IP40/IP67

Article no longer available - archive entry

Alternative articles: E80120

When selecting an alternative article and accessories please note that technical data may differ!

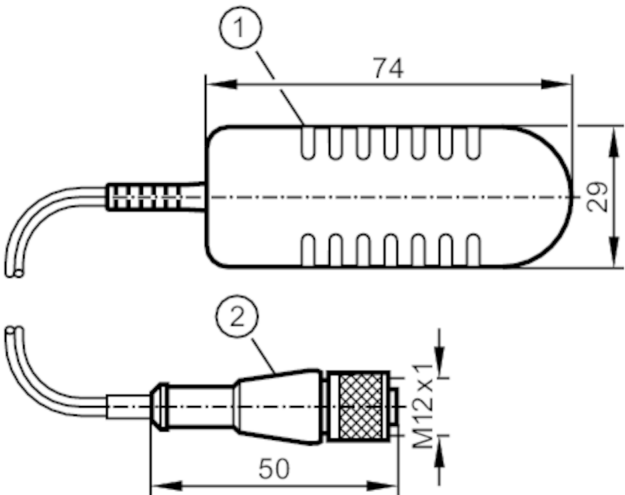

- 1 Power supply
2 M12 connector



Electrical data		
Nominal frequency AC	[Hz]	50...60
Input voltage range AC	[V]	100...240
Output voltage DC	[V]	24
Input current (nominal voltage 230 V AC / 50 Hz)	[A]	0.2
Outputs		
Output current, total	[A]	0.33
Operating conditions		
Protection	IP 40; (M12 connector: IP 67)	
Mechanical data		
Weight	[g]	135
Materials	PPE	
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 2 m; 2 x 0.5 mm²		
Connector: 1 x M12		