


# E30393



## Thermowell for temperature sensors

PROTECTIVE TUBE FOR TA

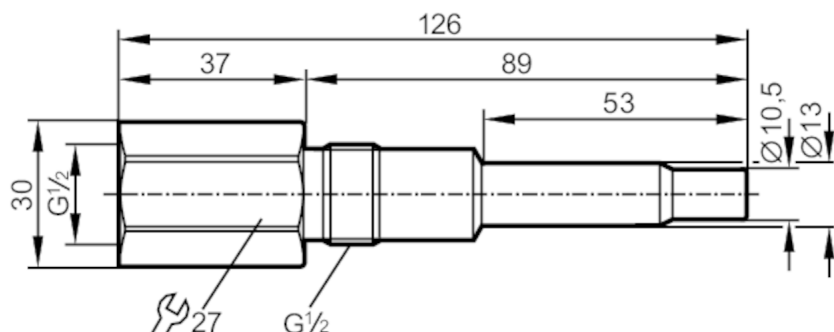

EC 1935/2004 EHEDG Tested FCM FDA

| Application                                       |                                                |
|---------------------------------------------------|------------------------------------------------|
| Design                                            | for temperature sensors TA34xx, TAA431, TAD191 |
| Pressure rating [bar]                             | 300                                            |
| Measuring/setting range                           |                                                |
| Probe length L [mm]                               | 53                                             |
| Mechanical data                                   |                                                |
| Weight [g]                                        | 172.9                                          |
| Materials                                         | stainless steel (1.4404 / 316L)                |
| Tightening torque [Nm]                            | 30...50                                        |
| Sensor connection                                 | G 1/2 sealing cone Ø 8,2 mm                    |
| Process connection                                | G 1/2                                          |
| Surface characteristics Ra/Rz of the wetted parts | < 0.6 / -                                      |
| Remarks                                           |                                                |
| Pack quantity                                     | 1 pcs.                                         |