


# E33405



## Process adapter Tri-Clamp

ADAPT G1/2 - 3A/DN38

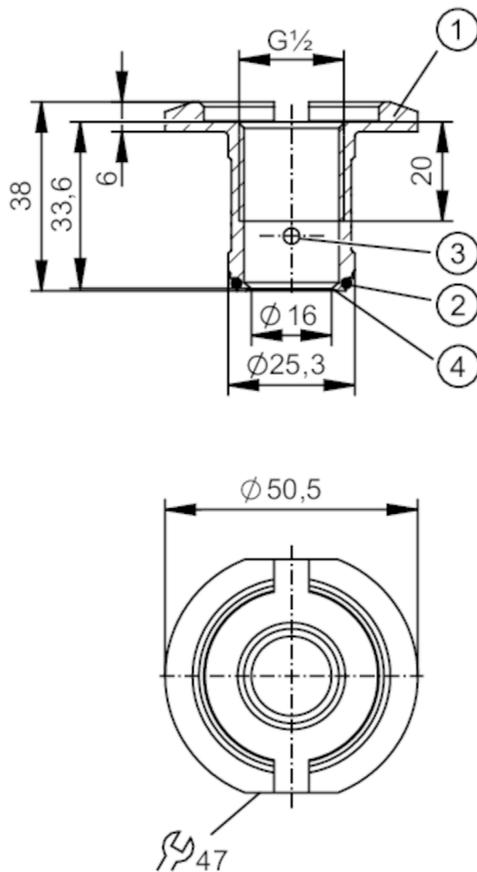

- 1 Adapter
- 2 Gasket
- 3 Leakage port
- 4 sealing edge



Application	
Pressure rating	[bar] 25
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight	[g] 142.5
Materials	stainless steel (1.4404 / 316L)
Sensor connection	G 1/2 sealing cone
Process connection	Clamp DN38 (1,5")
Surface characteristics Ra/Rz of the wetted parts	< 0.8 / 8
Sealing	metal to PEEK
Hygienic equipment class to DIN 11866	H3

# E33405



## Process adapter Tri-Clamp

ADAPT G1/2 - 3A/DN38

Аксессуары	
Items supplied	O-ring: 1, EPDM
Remarks	
Pack quantity	1 pcs.