


## Process adapter hygienic pipe fitting

ADAPT IFM-DIN11851 DN32/1.25"

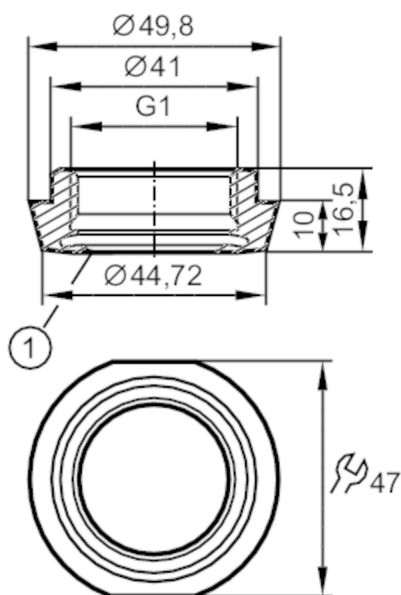

1 sealing edge

EC 1935/2004 FCM 

## Application

Pressure rating	[bar]	40
-----------------	-------	----

## Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

## Mechanical data

Weight	[g]	136
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 internal thread Aseptoflex Vario	
Process connection	hygienic pipe fitting DN32 (1,25") DIN 11851	
Sealing	metal to metal	
Hygienic equipment class to DIN 11866	H4	

## Remarks

Pack quantity	1 pcs.
---------------	--------