


## Process adapter Varivent

ADAPT IFM-VARIV TYP F (D=50)

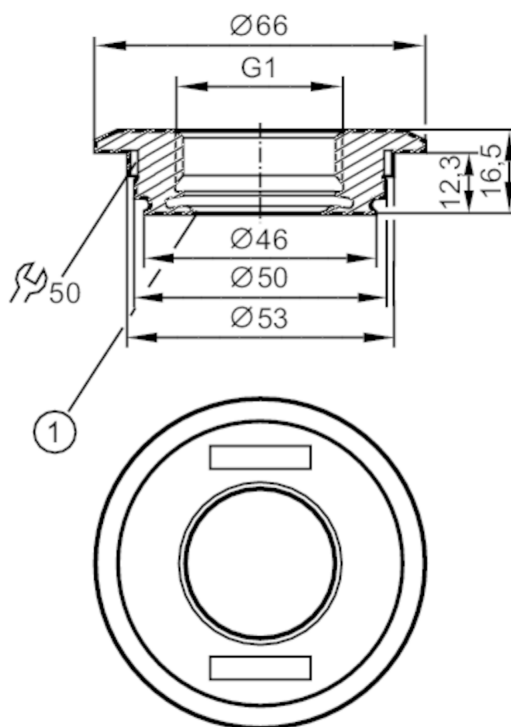

1 sealing edge

EC 1935/2004 FCM 

## Application

Pressure rating	[bar]	25
-----------------	-------	----

## Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

## Mechanical data

Weight	[g]	230
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 internal thread Aseptoflex Vario	
Process connection	Varivent Form F, DN25 (1"), Ø 50 mm	
Sealing	metal to metal	
Hygienic equipment class to DIN 11866	H4	

## Remarks

Pack quantity	1 pcs.
---------------	--------