



Process adapter Varivent


ADAP IFM-VARIV D=50(DN25/1)

Article no longer available - archive entry

Alternative articles: E33721

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

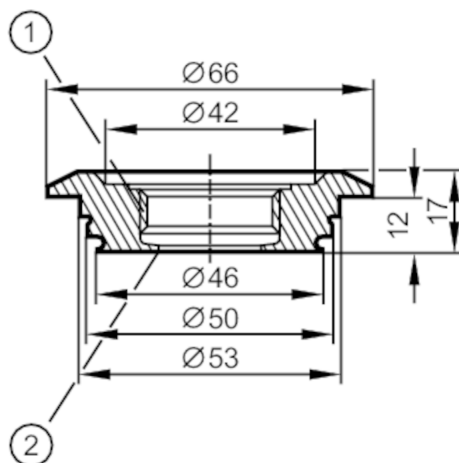

- 1 Aseptoflex thread
2 Aseptoflex sealing edge

EC 1935/2004 EHEDG Certified 

Application

Pressure rating [bar] 25

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]	241.8
Materials	stainless steel (1.4404 / 316L)
Sensor connection	Aseptoflex
Process connection	Varivent Form F, DN25 (1"), Ø 50 mm
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4

Remarks

Pack quantity 1 pcs.