



## Process adapter Varivent


ADA IFM-VARIV D=68(DN40-125)

Article no longer available - archive entry

Alternative articles: E33722

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

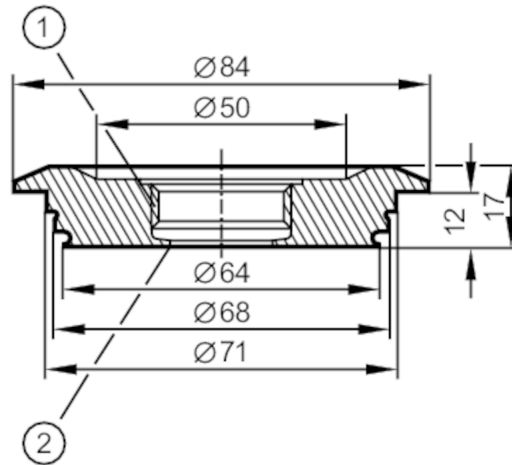

- 1 Aseptoflex thread  
2 Aseptoflex sealing edge

EC 1935/2004 EHEDG Tested FCM FDA

### Application

Pressure rating [bar] 25

### Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

### Mechanical data

Weight [g]	475.5
Materials	stainless steel (1.4404 / 316L)
Sensor connection	Aseptoflex
Process connection	Varivent Form N, DN40...DN150 (1,5...6"), Ø 68 mm
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4

### Remarks

Pack quantity 1 pcs.