


Mounting adapter for process sensors

ADAPT IFM-BREWERY D=48

Article no longer available - archive entry

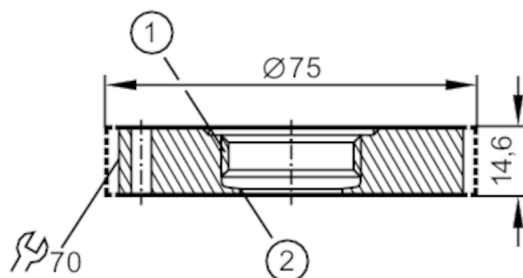

- 1 Aseptoflex thread
2 Aseptoflex sealing edge

Application

Pressure rating	[bar]	10
-----------------	-------	----

Mechanical data

Materials	stainless steel (1.4404 / 316L)
Sensor connection	Aseptoflex
Process connection	flange
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4

Remarks

Pack quantity	1 pcs.
---------------	--------