




Process adapter pipe fitting DIN 11864

ADAPT IFM-DIN11864-1A/DN50

Article no longer available - archive entry

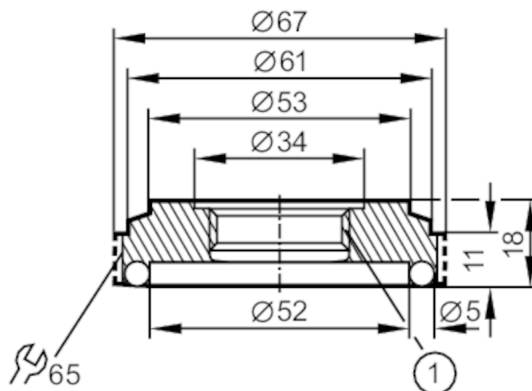

1 Aseptoflex thread

EC 1935/2004 

Application

Pressure rating	[bar]	25
-----------------	-------	----

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight	[g]	328.4
Materials	stainless steel (1.4404 / 316L)	
Sensor connection	Aseptoflex	
Process connection	Pipe fitting DN50 DIN 11864-1-A-BS	
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4	
Hygienic equipment class to DIN 11866	H4	

Remarks

Pack quantity	1 pcs.
---------------	--------