




## Process adapter hygienic pipe fitting

ADAPT IFM-DIN11851 DN32/1.25"

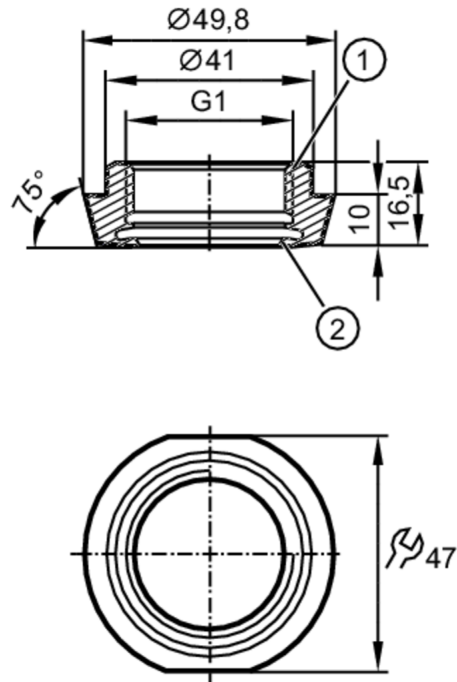

- 1 Aseptoflex Vario  
2 sealing area

EC 1935/2004 

Application		
Pressure rating	[bar]	40
Tests / approvals		
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.	
Safety instructions	The compatibility between medium and product material has to be checked in all applications.	
Mechanical data		
Weight	[g]	134
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 internal thread Aseptoflex Vario	
Process connection	hygienic pipe fitting DN32 (1,25") DIN 11851	
Sealing	Gasket	
Hygienic equipment class to DIN 11866	H4	
Аксессуары		
Items supplied	O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054	
Accessories (optional)	O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123	
	sealing ring: 1, PEEK, FDA compliant, E30124	
Remarks		
Pack quantity	1 pcs.	