




## T-piece

T-ADAPT G1 DN15

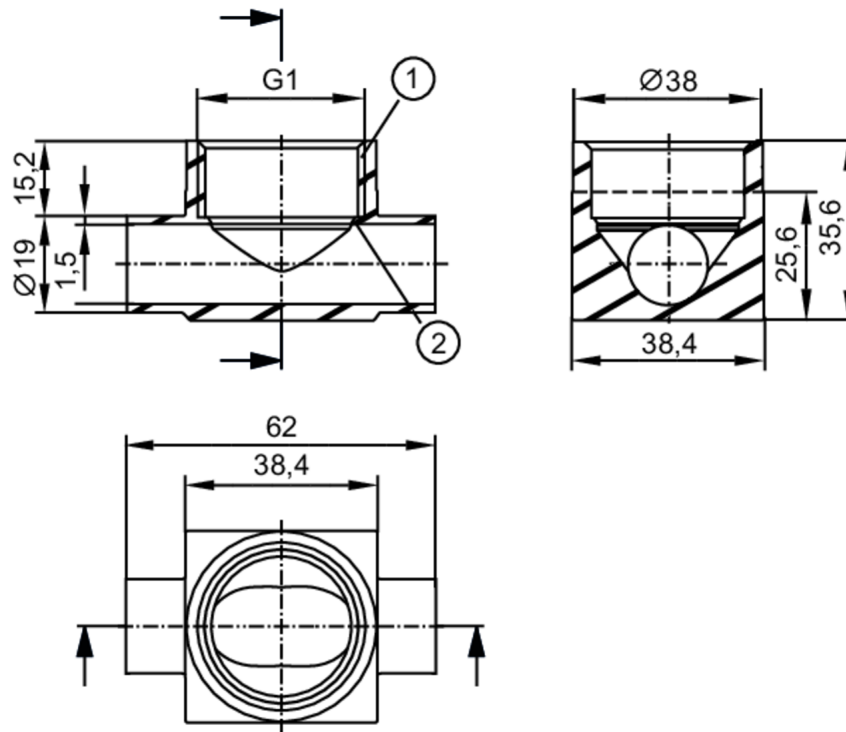

- 1 Aseptoflex Vario  
2 sealing area

EC 1935/2004 

## Application

Pressure rating	[bar]	25
Note on pressure rating	for the connection sensor - adapter	

## Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.	
Safety instructions	The compatibility between medium and product material has to be checked in all applications.	

## Mechanical data

Weight	[g]	273.5
Materials (wetted parts)	stainless steel (1.4404 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 Aseptoflex Vario	
Process connection	welding adapter Ø 19 mm	
Sealing	Gasket	

## Аксессуары

Items supplied	O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054
Accessories (optional)	O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123

## Remarks

Pack quantity	1 pcs.
---------------	--------