


Thermowell for temperature sensors

HYGIENIC THERMOWELL L=050

Article no longer available - archive entry

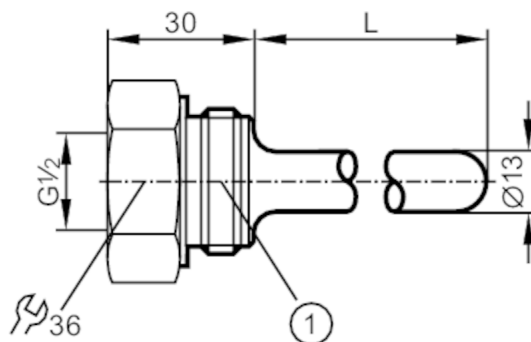

1 Aseptoflex thread



EC 1935/2004 EHEDG Tested FDA

Application

Design	for temperature sensors Ø 10 mm
Application	hygienic systems
Recommended media	viscous media and liquids with suspended particles
Pressure rating [bar]	25

Measuring/setting range

Probe length L [mm]	45
---------------------	----

Mechanical data

Weight [g]	173.5
Materials	stainless steel (1.4404 / 316L)
Sensor connection	G 1/2 Ø 10 mm
Process connection	Aseptoflex
Surface characteristics Ra/Rz of the wetted parts	< 0.6 / -

Remarks

Pack quantity	1 pcs.
---------------	--------