

E40041




Wirable socket

SDOGH050PLSFKPG

Article no longer available - archive entry

Alternative articles: E11511
When selecting an alternative article and accessories please note that technical data may differ!

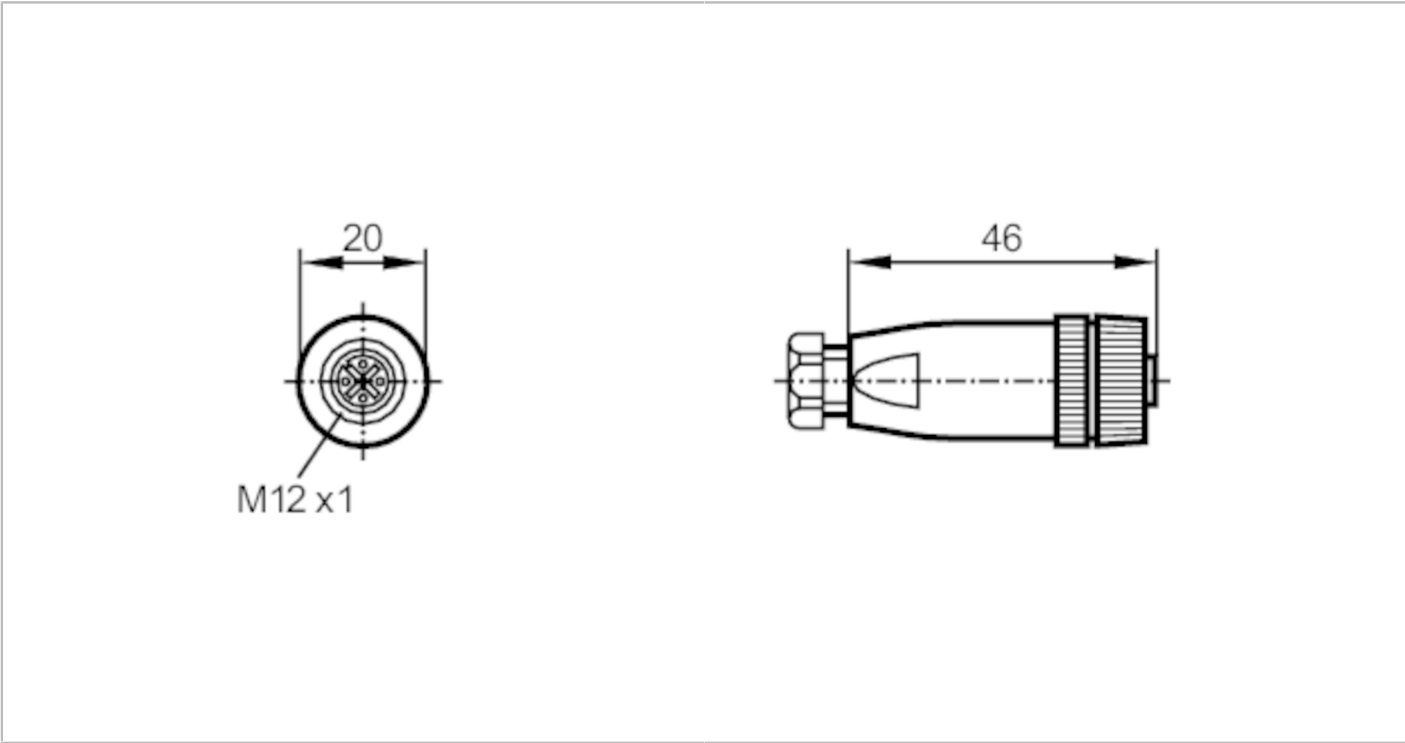

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	20 x 20 x 46
Materials		PA
Moulded-body material		PA
Material nut		PA
Remarks		
Pack quantity		1 pcs.

E40041



Wirable socket


SDOGH050PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: PA

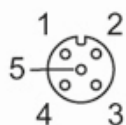

Connection

